


Molle carico leggero  
Light load springs  
Federn für normale belastung  
Ressorts charge légère

Serie **TV**  
Series  
Serie  
Série

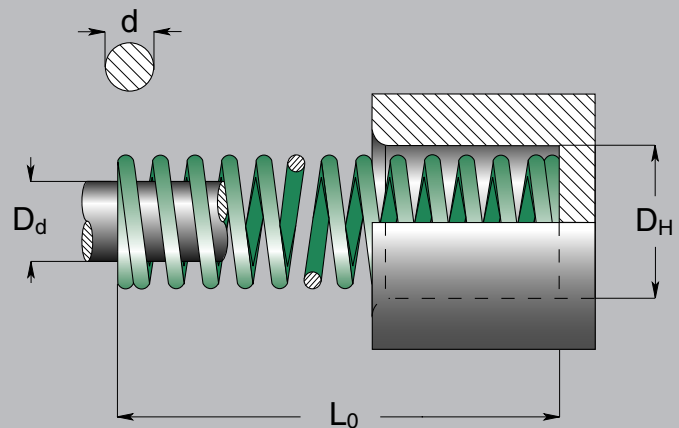

D <sub>H</sub>	D <sub>d</sub>	L <sub>0</sub>	N. di catalogo Catalogue No. Bestellnummer N° de catalogue	Rigidità Rate Rigidez Raideur	25%		30%		40%		D	
					3.000.000	1.500.000	Max. Defl.		Approx.			
mm	mm	mm		N / mm	mm	N	mm	N	mm	N	mm	N
10	5	25	TV 10 - 025	4.4	6.3	28	7.5	33	10.0	44	13.2	58
		32	TV 10 - 032	3.4	8.0	27	9.6	33	12.8	44	16.5	58
		38	TV 10 - 038	2.8	9.5	26	11.4	32	15.2	42	19.8	53
		44	TV 10 - 044	2.4	11.0	26	13.2	31	17.6	42	23.1	53
		51	TV 10 - 051	2.1	12.8	27	15.3	32	20.4	43	26.9	58
		64	TV 10 - 064	1.6	16.0	26	19.2	31	25.6	42	33.3	53
		76	TV 10 - 076	1.3	19.0	25	22.8	30	30.4	40	39.6	53
1.1	305	TV 10 - 305	0.3	76.3	24	91.5	29	122.0	38	157.2	49	
12.5	6.3	25	TV 13 - 025	8.5	6.3	53	7.5	64	10.0	85	13.5	116
		32	TV 13 - 032	6.5	8.0	52	9.6	62	12.8	83	16.8	111
		38	TV 13 - 038	5.3	9.5	51	11.4	61	15.2	81	20.3	107
		44	TV 13 - 044	4.4	11.0	49	13.2	59	17.6	78	23.9	107
		51	TV 13 - 051	3.8	12.8	48	15.3	58	20.4	78	26.9	102
		64	TV 13 - 064	2.9	16.0	47	19.2	56	25.6	75	33.3	98
		76	TV 13 - 076	2.5	19.0	48	22.8	57	30.4	76	41.1	102
1.5	89	TV 13 - 089	2.1	22.3	48	26.7	57	35.6	76	48.3	102	
305	TV 13 - 305	0.6	76.3	45	91.5	54	122.0	73	162.8	93		
16	8	25	TV 16 - 025	17.9	6.3	112	7.5	134	10.0	179	14.7	262
		32	TV 16 - 032	13.5	8.0	108	9.6	129	12.8	173	18.5	249
		38	TV 16 - 038	10.5	9.5	100	11.4	120	15.2	160	22.4	236
		44	TV 16 - 044	8.8	11.0	96	13.2	116	17.6	154	25.9	227
		51	TV 16 - 051	7.6	12.8	97	15.3	116	20.4	155	30.0	227
		64	TV 16 - 064	5.9	16.0	95	19.2	114	25.6	152	37.8	222
		76	TV 16 - 076	4.8	19.0	91	22.8	109	30.4	145	45.2	218
2	89	TV 16 - 089	4.0	22.3	90	26.7	108	35.6	144	52.8	214	
102	TV 16 - 102	3.5	25.5	90	30.6	108	40.8	144	60.7	214		
305	TV 16 - 305	1.1	76.3	85	91.5	103	122.0	137	183.9	205		

Note: 1 N = 0,102 Kg (force)